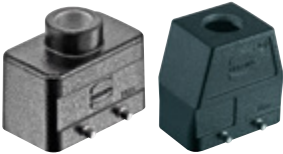
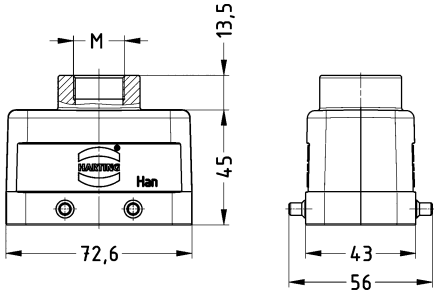
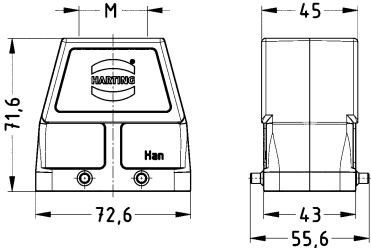
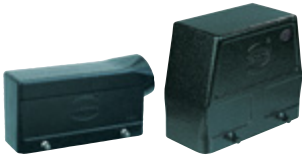
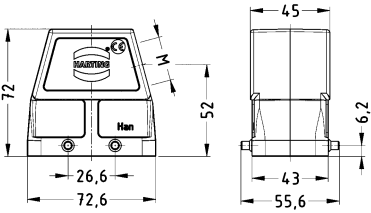
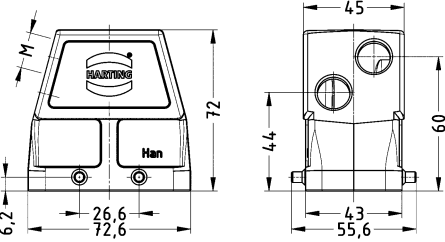


Hoods/housings for rough environments
Double locking lever

Housings

| Identification | Cable entry | Part number | | Drawing (dimensions in mm) |
|--|--|------------------|--|--|
| | | Low construction | High construction | |
| Han® M, Hood, Top entry, IP65, IP66, IP67  | 1x M20 1x M25 1x M32 2x M20 | 19 37 010 1420 | 19 37 010 0426 19 37 010 0427 19 37 010 0465 |   |
| Han® M, Hood, Side entry, IP65, IP66, IP67  | 1x M20 1x M25 1x M32 1x M40 2x M16 | 19 37 010 1520 | 19 37 010 0526 19 37 010 0527 19 37 010 0528 19 37 010 0564 |   |