 
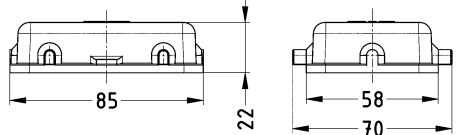
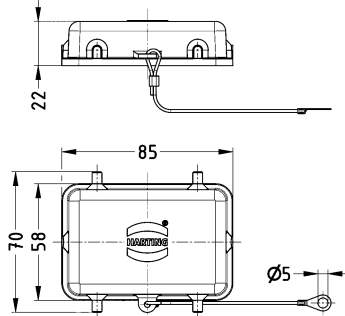


| Identification                                                                                                                                                                                                                            | Cable entry | Part number      |                   | Drawing<br>(dimensions in mm)                                                        |
|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-------------|------------------|-------------------|--------------------------------------------------------------------------------------|
|                                                                                                                                                                                                                                           |             | Low construction | High construction |                                                                                      |
| Han A®,<br>Protection cover,<br>for hoods,<br>Metal,<br>IP65<br><br>                                                                                     |             | 09 20 032 5401   | 09 20 032 5401    |    |
| Han A®,<br>Protection cover,<br>for bulkhead mounted housings,<br>for surface mounted housings,<br>Metal,<br>IP65<br><br>                                |             | 09 20 032 5405   | 09 20 032 5405    |    |
| Han A®,<br>Protection cover,<br>for bulkhead mounted housings,<br>for surface mounted housings,<br>Thermoplastic,<br>IP65<br><br>                      |             | 09 20 032 5407   | 09 20 032 5407    |   |
| Han A®,<br>Protection cover,<br>for bulkhead mounted housings,<br>for surface mounted housings,<br>Thermoplastic,<br>With fixing cord,<br>IP65<br><br> |             | 09 20 032 5408   | 09 20 032 5408    |  |