
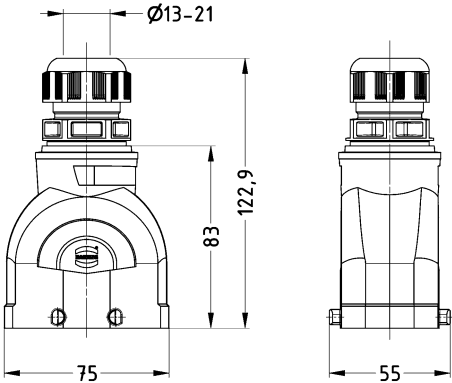

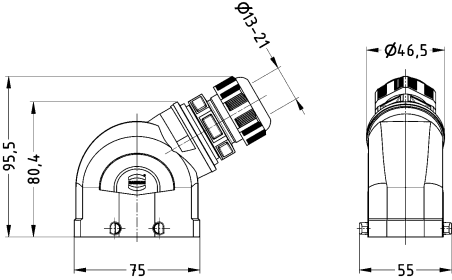

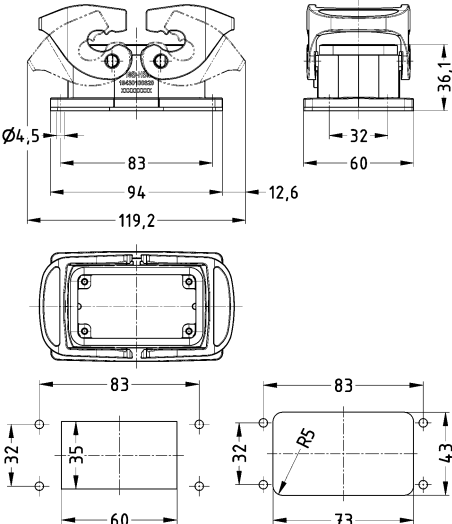


Double locking lever

Han Eco

Identification	Cable entry	Clamping range (mm)	Part number	Drawing (dimensions in mm)
<p>Han-Eco® B, Hood, With integrated cable gland, Top entry, IP66</p> 	<p>1x M20 1x M25 1x M32</p>	<p>6 ... 13 9 ... 17 13 ... 21</p>	<p>19 43 110 0425 19 43 110 0426 19 43 110 0427</p>	
<p>Han-Eco® B, Hood, With integrated cable gland, Side entry, IP66</p> 	<p>1x M20 1x M25 1x M32</p>	<p>6 ... 13 9 ... 17 13 ... 21</p>	<p>19 43 110 0525 19 43 110 0526 19 43 110 0527</p>	
<p>Han-Eco® B, Bulkhead mounted housing, IP66</p> 			<p>19 43 010 0320</p>	 <p>Panel cut out Front mounting / Rear mounting</p>