
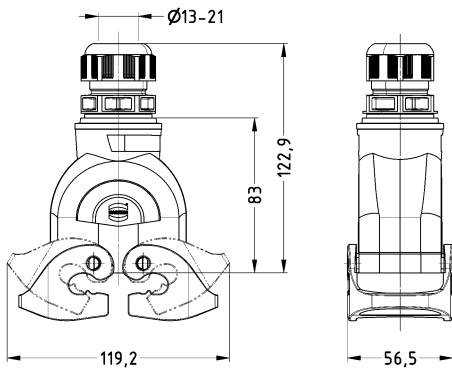

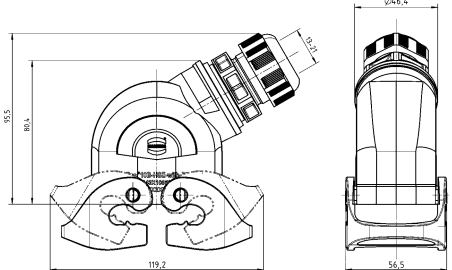

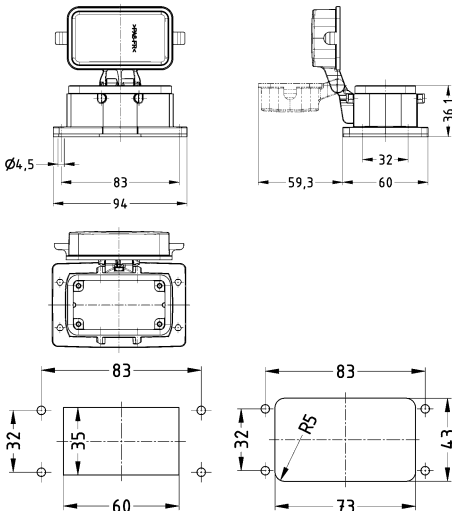


Double locking lever (on the hood)

Han  
Eco

Identification	Cable entry	Clamping range (mm)	Part number	Drawing (dimensions in mm)
Han-Eco® B, Hood, With integrated cable gland, Top entry, IP66  	1x M32	13 ... 21	19 43 110 0437	
Han-Eco® B, Hood, With integrated cable gland, Side entry, IP66  	1x M32	13 ... 21	19 43 110 0537	
Han-Eco® B, Bulkhead mounted housing, With thermo-plastic cover, IP66  			19 43 010 0322	 <p data-bbox="963 1912 1286 1962">Panel cut out Front mounting / Rear mounting</p>