



Han® PushPull L Power 4/0 Coupling Metal

Features

- High degree of protection IP65 / IP67
- Robust metal housing
- Standard PROFINET component of the German automotive production
- Extension of cords according to PROFINET guideline
- For an easy robot termination and a fast exchange of tube packages

Technical characteristics

Locking	PushPull technology
Electrical transmission	16 A / 24 V
Number of contacts	5
Mating cycles	min. 500
Housing material	Aluminium die-cast
Degree of protection acc. to DIN 60529	IP65 / IP67
Temperature range	-40 °C ... +70 °C

Identification

Part number



Drawing

Dimensions in mm

Han® PushPull L Power 4/0 Coupling metal

including housing, contact insert Power L, bulkhead housing and cable gland

61 04 201 1085

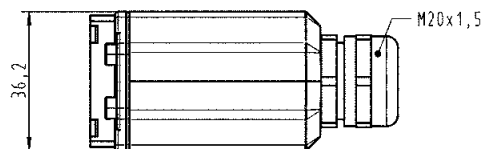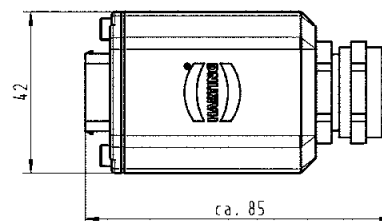

Fixing flange

61 04 600 0183

