




M8 System cables 3 and 4 poles

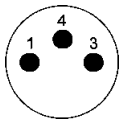


Male, 3 poles

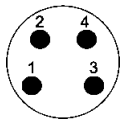

Male, 4 poles

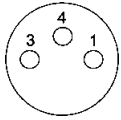

Female, 3 poles

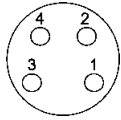

Female, 4 poles



Circular Connectors

Part number definition



- Connector 1**
- 80 Male straight
 - 81 Female straight
 - 82 Male angled
 - 83 Female angled

- Connector 2**
- 00 No connector
 - 80 Male straight
 - 81 Female straight
 - 82 Male angled
 - 83 Female angled

- Number of contacts**
- 3 3 poles
 - 4 4 poles

- Cable material**
- 80 PVC (3 poles)
 - 81 PVC (4 poles)
 - 88 PUR (3 poles)
 - 89 PUR (4 poles)

- Preferred length***
- 005 0.5 m
 - 010 1.0 m
 - 015 1.5 m
 - 020 2.0 m
 - 050 5.0 m
 - 075 7.5 m
 - 100 10.0 m

* Other length on request