




Mating face

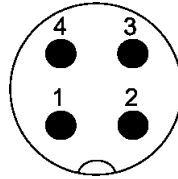

A-coding  
Mating face  
acc. to IEC 61076-2-101



Circular Connectors

Identification	Part number	Drawing	Dimensions in mm
----------------	-------------	---------	------------------

**HARAX® M12-L, unshielded**



Male  
3 poles, A-coding,  
with pre-leading contact  
(assignment 3, 4, 5)

21 03 212 1400

3 poles, A-coding  
(assignment 1, 3, 4)

21 03 212 1306


4 poles, A-coding  
(assignment 1, 2, 3, 4)

21 03 212 1305

4 poles, A-coding,  
to 2.6 mm core diameter  
(assignment 1, 2, 3, 4)

21 03 212 1407

0.34 - 0.75 mm<sup>2</sup>  
AWG 22 - 18  
Cable diameter: 6 - 8 mm

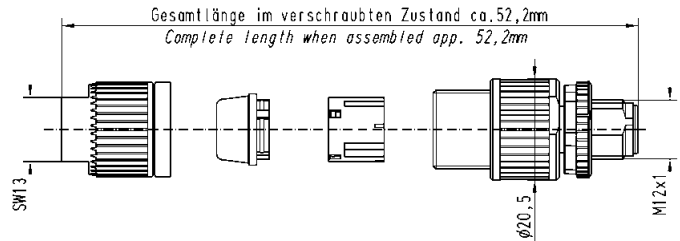

**HARAX® M12-L, unshielded**



Male  
5 poles, A-coding

21 03 272 1505

0.34 - 0.5 mm<sup>2</sup>  
AWG 22 - 20  
Cable diameter: 6 - 8 mm

