


Number of contacts

78+2, 60+4, 42+6, 24+8, 6+10

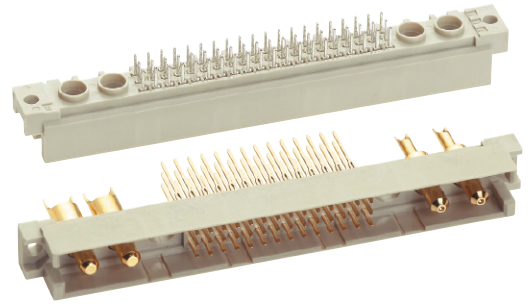

Male connectors

DIN Signal
up to 2 A

Identification	No. of contacts	Contact arrangement	Part number	Performance levels according to IEC 60603-2. Explanation chapter 00		
				3	2	1
Male connector with solder pins 2.5 mm	78 + 2		Performance level 3 on request	09 73 178 6902	Performance level 1 on request	
	60 + 4			09 73 160 6902		
	42 + 6			09 73 142 6902		
	24 + 8			09 73 124 6902		
	6 + 10			09 73 106 6902		
Male connector with solder pins 4.0 mm	78 + 2			09 73 178 6903		
	60 + 4			09 73 160 6903		
	42 + 6			09 73 142 6903		
	24 + 8			09 73 124 6903		
	6 + 10			09 73 106 6903		
Male connector with solder pins 6.0 mm	78 + 2			09 73 178 6991		
	60 + 4			09 73 160 6991		
	42 + 6			09 73 142 6991		
	24 + 8			09 73 124 6991		
	6 + 10			09 73 106 6991		
Male connector with wrap posts 13 mm	78 + 2		09 73 178 6907			
	60 + 4		09 73 160 6907			
	42 + 6		09 73 142 6907			
	24 + 8		09 73 124 6907			
	6 + 10		09 73 106 6907			
Male connector with press-in pins 13 mm (5.0 mm on request)	78 + 2		09 73 178 6974●			
	60 + 4		09 73 160 6974●			
	42 + 6		09 73 142 6974●			
	24 + 8		09 73 124 6974●			
	6 + 10		09 73 106 6974●			