


Number of contacts

# 20

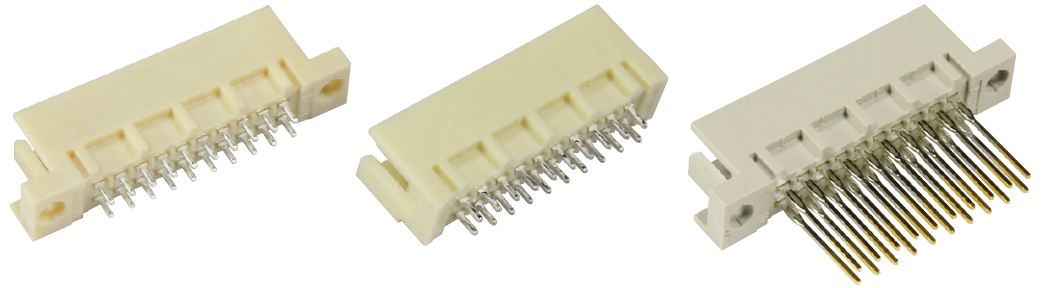

Male connectors

Identification	No. of contacts	Contact arrangement	Part number	Performance levels according to IEC 60603-2. Explanation chapter 00
			3	2 1
Male connector with press-in pins 13 mm with fixing flange	20		Performance level 3 on request	09 75 120 6985 <sup>w)</sup> 09 75 120 6974 <sup>*</sup>
without fixing flange	20			09 75 120 6574 <sup>*</sup>

DIN Signal up to 2 A

Identification Drawing Dimensions in mm

**Dimensions**

a	b	
2.5	∅ 0.7	Solder pins
4		
13	□ 0.6	Wrap posts
13	□ 0.6	
5	-	Press-in pins
13	-	

**Panel cut out**

	Y
Solder	1 ± 0.1
Press-in	see recommendation page 00.25

**Board drillings**  
Mounting side

**Cross section of solder terminations**

Cross area (A) of contacts row a, b: A = 0.35 - 0.39 mm<sup>2</sup>

Other contact arrangements as well with lagging/leading pins on request  
 • Wrap posts for interfacing selectively gold plated (performance level 3)  
 w) Wrap posts not for interfacing, no performance level