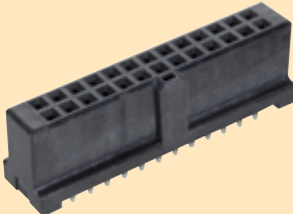


PCB distance	Type	Pictures	Number of contacts	Performance level	Female			Male			
					Termination length (mm)	Termination*	Part number	Part number	Termination*	Termination length (mm)	
14.7 - 16.7 mm	SEK		16	PL2	2.9	THT THR	09 19 516 6824	09 18 516 6324 09 19 516 6324	THT THR	2.9	
						THR (T&R)	09 19 516 6824741	09 19 516 6324740 09 19 516 6324741	THR (T&R)		
					4.5	THT THR	09 19 516 6822	09 18 516 6322 09 19 516 6322	THT THR	4.5	
				Press-in		09 19 516 6829	09 18 516 6329	Press-in	5.5		
				PL3	2.9	THT THR	09 19 516 7824	09 18 516 7324 09 19 516 7324	THT THR	2.9	
						THR (T&R)	09 19 516 7824741	09 19 516 7324740 09 19 516 7324741	THR (T&R)		
			4.5		THT THR	09 19 516 7822	09 18 516 7322 09 19 516 7322	THT THR	4.5		
				Press-in	09 19 516 7829	09 18 516 7329	Press-in	5.5			
				20	PL2	2.9	THT THR	09 19 520 6824	09 18 520 6324 09 19 520 6324	THT THR	2.9
							THR (T&R)	09 19 520 6824741	09 19 520 6324740 09 19 520 6324741	THR (T&R)	
						4.5	THT THR	09 19 520 6822	09 18 520 6322 09 19 520 6322	THT THR	4.5
					Press-in		09 19 520 6829	09 18 520 6329	Press-in	5.5	
		PL3			2.9	THT THR	09 19 520 7824	09 18 520 7324 09 19 520 7824	THT THR	2.9	
						THR (T&R)	09 19 520 7824741	09 19 520 7324740 09 19 520 7324741	THR (T&R)		
				4.5	THT THR	09 19 520 7822	09 18 520 7322 09 19 520 7322	THT THR	4.5		
		Press-in			09 19 520 7829	09 18 520 7329	Press-in	5.5			
				26	PL2	2.9	THT THR	09 19 526 6824	09 18 526 6324 09 19 526 6324	THT THR	2.9
							THR (T&R)	09 19 526 6824741	09 19 526 6324740 09 19 526 6324741	THR (T&R)	
						4.5	THT THR	09 19 526 6822	09 18 526 6322 09 19 526 6322	THT THR	4.5
					Press-in		09 19 526 6829	09 18 526 6329	Press-in	5.5	
			PL3		2.9	THT THR	09 19 526 7824	09 18 526 7324 09 19 526 7324	THT THR	2.9	
						THR (T&R)	09 19 526 7824741	09 19 526 7324740 09 19 526 7324741	THR (T&R)		
				4.5	THT THR	09 19 526 7822	09 18 526 7322 09 19 526 7322	THT THR	4.5		
			Press-in		09 19 526 7829	09 18 526 7329	Press-in	5.5			

*Terminations: THT = through hole technology (Wave Solder); THR =through hole reflow; T&R = tape&reel packaging