
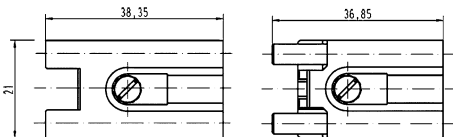
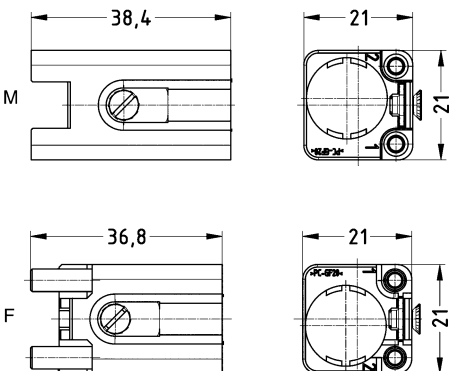


Number of contacts

1,4,8

+ shielding + 2 power contacts

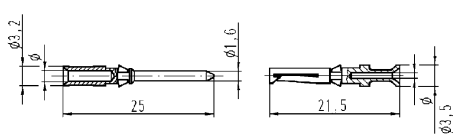

Identification	Conductor cross-section (mm²)	Part number		Drawing (dimensions in mm)																					
		Male	Female																						
Han-Brid®, Han-Brid® Quintax 3 A, Crimp termination 	0.14 ... 2.5	09 15 003 3001	09 15 003 3101																						
Please order crimp contacts separately.																									
Han-Brid®, Han-Brid® Quintax 3 A, Snap-in latches, snap-fit, Crimp termination 	0.14 ... 2.5	09 15 003 3002	09 15 003 3102																						
Please order crimp contacts separately.																									
Han D®, Crimp contact, Contact surface: Gold plated 	0.14 ... 0.37 0.5 0.75 1 1.5 2.5	09 15 000 6124 09 15 000 6123 09 15 000 6125 09 15 000 6122 09 15 000 6121 09 15 000 6126	09 15 000 6224 09 15 000 6223 09 15 000 6225 09 15 000 6222 09 15 000 6221 09 15 000 6226	 <table><tr><th>Conductor cross-section</th><th>ø</th><th>Stripping length</th></tr><tr><td>0.14-0.37 mm² AWG 26-22</td><td>0.9 mm</td><td>8 mm</td></tr><tr><td>0.5 mm² AWG 20</td><td>1.1 mm</td><td>8 mm</td></tr><tr><td>0.75 mm² AWG 18</td><td>1.3 mm</td><td>8 mm</td></tr><tr><td>1 mm² AWG 18</td><td>1.45 mm</td><td>8 mm</td></tr><tr><td>1.5 mm² AWG 16</td><td>1.75 mm</td><td>8 mm</td></tr><tr><td>2.5 mm² AWG 14</td><td>2.25 mm</td><td>6 mm</td></tr></table>	Conductor cross-section	ø	Stripping length	0.14-0.37 mm² AWG 26-22	0.9 mm	8 mm	0.5 mm² AWG 20	1.1 mm	8 mm	0.75 mm² AWG 18	1.3 mm	8 mm	1 mm² AWG 18	1.45 mm	8 mm	1.5 mm² AWG 16	1.75 mm	8 mm	2.5 mm² AWG 14	2.25 mm	6 mm
Conductor cross-section	ø	Stripping length																							
0.14-0.37 mm² AWG 26-22	0.9 mm	8 mm																							
0.5 mm² AWG 20	1.1 mm	8 mm																							
0.75 mm² AWG 18	1.3 mm	8 mm																							
1 mm² AWG 18	1.45 mm	8 mm																							
1.5 mm² AWG 16	1.75 mm	8 mm																							
2.5 mm² AWG 14	2.25 mm	6 mm																							