

Standard Hoods/housings for industrial applications  
Single locking lever

Han-Brid

## Features

- Hoods/housings for industrial applications
- With glued seal

## Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP44, IP65 / IP67, with seal screw 09 20 000 9918
Type rating acc. to UL 50 / UL 50E	12
Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 7037 (dust grey)
Material (seal)	NBR
RoHS	compliant with exemption, compliant


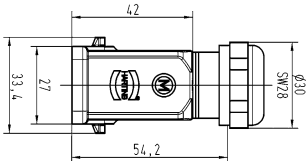

## Specifications and approvals

DNV GL



## Details

The special hoods with glued seal can be combined with standard housings (see chapter Han 31).

Identification	Cable entry	Cable diameter (mm)	Part number	Drawing (dimensions in mm)
Han A®, Hood, for Han-Brid®, With glued seal, With integrated cable gland, Top entry, IP44, IP65 / IP67 with seal screw 09 20 000 9918 	1x Integrated 1x Integrated	5 ... 13 6 ... 12	19 20 003 1423 19 20 003 1425	
Han A®, Hood, for Han-Brid®, With glued seal, Top entry, IP44, IP65 / IP67 with seal screw 09 20 000 9918 	1x M20 1x M25		19 20 003 1443 19 20 003 1447	