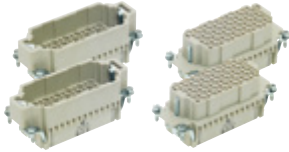
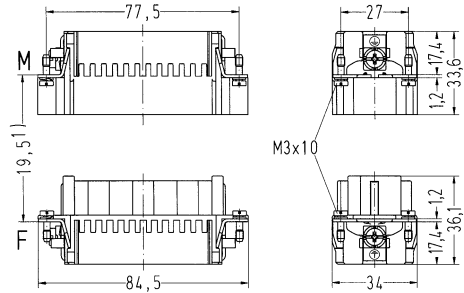
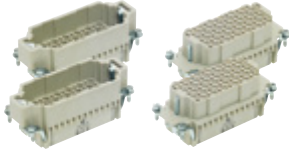
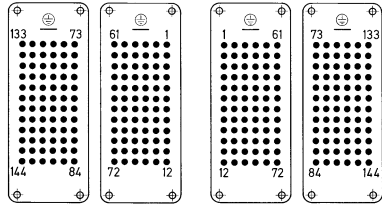
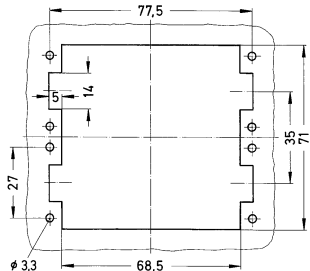


Number of contacts

144+

10 A 250 V 4 kV 3

Identification	Conductor cross-section (mm ²)	Part number		Drawing (dimensions in mm)
		Male	Female	
<p>Han DD®, Crimp termination, 1 ... 72</p>  <p>Please order crimp contacts separately. You need two inserts for a complete assembly!</p>	0.14 ... 2.5	09 16 072 3001	09 16 072 3101	 <p>1) distance for contact max. 21 mm</p>
<p>Han DD®, Continuing marking, Crimp termination, 73 ... 144</p>  <p>Please order crimp contacts separately. You need two inserts for a complete assembly!</p>	0.14 ... 2.5	09 16 072 3011	09 16 072 3111	 <p>Contact arrangement (view from termination side)</p>  <p>Panel cut out for use without Hoods/Housings</p>