
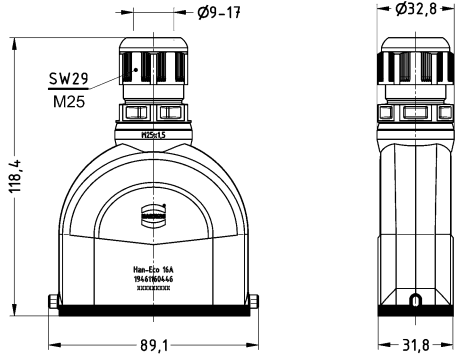

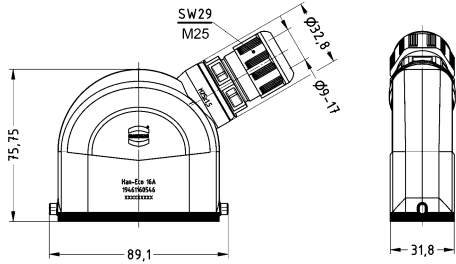

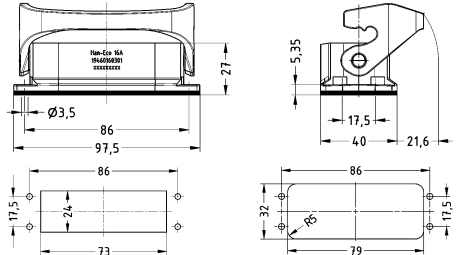


Single locking lever



Han Eco

Identification	Cable entry	Clamping range (mm)	Part number	Drawing (dimensions in mm)
<p>Han-Eco® A, Hood, With integrated cable gland, Top entry, IP65</p> 	<p>1x M20 1x M25</p>	<p>6 ... 13 9 ... 17</p>	<p>19 46 316 0445 19 46 316 0446</p>	
<p>Han-Eco® A, Hood, With integrated cable gland, Side entry, IP65</p> 	<p>1x M20 1x M25</p>	<p>6 ... 13 9 ... 17</p>	<p>19 46 316 0545 19 46 316 0546</p>	
<p>Han-Eco® A, Bulkhead mounted housing, IP65</p> 			<p>19 46 216 0301</p>	 <p>Panel cut out Front mounting / Rear mounting</p>