


Number of contacts

48, 32

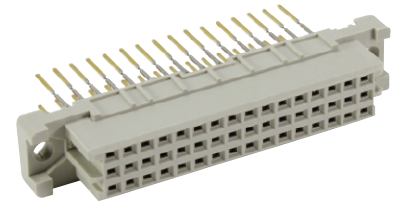

Female connectors

Identification	No. of contacts	Contact arrangement	Performance levels according to IEC 60603-2. Explanation chapter 00		
			3	2	1
Female connector with press-in pins 3.7 mm	48			09 23 248 6866	
Female connector with press-in pins 4.5 mm	48 32			09 23 248 6850 09 23 248 6850 222 ^{f)} 09 23 232 6850	09 23 248 2850
Female connector with press-in pins 13 mm	48 32			09 23 248 6861 09 23 232 6861	
Female connector with press-in pins 17 mm	48			09 23 248 6862	
with press-in terminations for rear interfacing Usage of HARTING shroud recommended: contacts for rear interfacing selectively gold plated (performance level 3)					

Identification	No. of contacts	Part number	Drawing	Dimensions in mm
Female connector for crimp contacts Order contacts separately see page 01.28				
Type 2C	48	09 23 048 3214 ^{f)}		
Type 2C Position marking turned for mating type 2R male	48	09 23 048 3217 ^{f)}		

Other contact arrangements on request

^{f)} Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2