


PCB terminal blocks,  
vertical with push-in-spring-cage  
termination  
pitch 5.00 mm

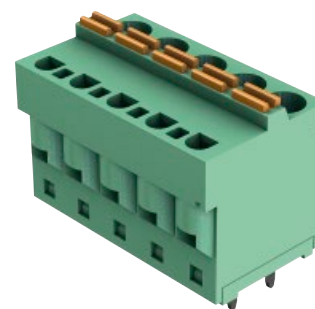

| Identification                                                           | No. of contacts | Part No.           | Packaging unit (pieces) |
|--------------------------------------------------------------------------|-----------------|--------------------|-------------------------|
| PCB terminal blocks,<br>vertical with push-in-spring-cage<br>termination | 2               | 14 03 021 6101 000 | 300                     |
|                                                                          | 3               | 14 03 031 6101 000 | 200                     |
|                                                                          | 4               | 14 03 041 6101 000 | 150                     |
|                                                                          | 5               | 14 03 051 6101 000 | 150                     |
|                                                                          | 6               | 14 03 061 6101 000 | 100                     |
|                                                                          | 7               | 14 03 071 6101 000 | 100                     |
|                                                                          | 8               | 14 03 081 6101 000 | 100                     |
|                                                                          | 9               | 14 03 091 6101 000 | 100                     |
|                                                                          | 10              | 14 03 101 6101 000 | 100                     |
|                                                                          | 11              | 14 03 111 6101 000 | 100                     |
|                                                                          | 12              | 14 03 121 6101 000 | 100                     |
|                                                                          | 13              | 14 03 131 6101 000 | 50                      |
|                                                                          | 14              | 14 03 141 6101 000 | 50                      |
|                                                                          | 15              | 14 03 151 6101 000 | 50                      |
|                                                                          | 16              | 14 03 161 6101 000 | 50                      |
|                                                                          | 17              | 14 03 171 6101 000 | 50                      |
|                                                                          | 18              | 14 03 181 6101 000 | 50                      |